

## PSSu BP-C1 1/12 C

312623




PSSu, base module for electronic modules, periphery, C-rail, 1-row, 6 connection levels, 12 terminals, spring-loaded connection. All the internal 7 signals are present at the terminals!

## Technical details

| General data                   |                                |
|--------------------------------|--------------------------------|
| Approval:                      | CE, UKCA,                      |
| Technical data                 |                                |
| Mechanical data                |                                |
| Net weight:                    | 46                             |
| Gross weight:                  | 59                             |
| Environment                    |                                |
| RoHS directive:                | 2011/65/EU, 2015/863/EU        |
| RoHS conformity:               | yes                            |
| RoHS exceptions:               | yes                            |
| RoHS except.s acc. to direct.: | 6c                             |
| REACH compliance:              | contains min. 1 SVHC-substance |
| REACH included substances:     | Lead                           |
| %-part of the pollutant:       | > 0,1%                         |
| CAS No.:                       | 7439-92-1                      |
| WEEE classification (08/2018): | 5 devices (feed size < 50cm)   |
| SCIP entry available:          | yes                            |
| Commercial data                |                                |
| Harmonized System Code:        | 85369095                       |
| UNSPSC 25:                     | 39122331                       |

|                           |               |
|---------------------------|---------------|
| EAN-Code:                 | 4046548058482 |
| ECLASS version:           | ECLASS-13     |
| ECLASS Reference Feature: | 27242603      |
| ETIM Version:             | ETIM-9.0      |
| ETIM Reference Group:     | EG000024      |
| ETIM Reference Feature:   | EC001598      |
| Volume:                   | 0             |

## Optional accessories

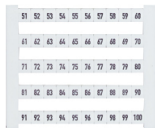


312960

PSSu A LA2 ( 10x50 pcs.)



312951

PSSu A ME1 (10x6 pcs.)

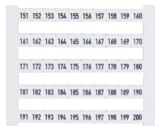


312962

PSSu A LA4 (10x50 pcs.)



312950

PSSu A ME0 (10x6 pcs.)

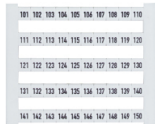

312961

PSSu A LA3 (10x50 pcs.)



312953

PSSu A ME3 (10x6 pcs.)



312952

PSSu A ME2 (10x6 pcs.)



312963

PSSu A SH S (10 pcs.)



312955

PSSu A ME5 (10x6 pcs.)



 
312900

PSSu A ET (10 pcs.)



312954

PSSu A ME4 (10x6 pcs.)



312957

PSSu A ME7 (10x6 pcs.)



312902

PSSu A EC



312956

PSSu A ME5 (10x6 pcs.)



312901

PSSu A ETM (2 pcs.)



312967

PSSu A LA0.1 (10 x 108 pcs.)



312959

PSSu A LA1 (10x50 pcs.)



312958

PSSu A LA0 (10 x 108 pcs.)



312949

PSSu A ET PE (10 pcs.)