

PSSu BP-C 1/8 C-J

312613



PSSu, base module for electronic modules, periphery, C-rail, 1-row, 4 connection levels, 8 terminals, spring-loaded connection, cold junction compensation with integral Pt1000.

Technical details

General data

Approval:	CE, UKCA,
Application range:	Standard/failsafe

Technical data

Environmental data

Humidity rating:	93 % r. h. at 40 °C
Condensation permitted?:	Not permitted
Vibration to standard ...:	EN 60068-2-6
Acc. shock to standard1:	15g

Mechanical data


Housing material lower section:	PA
Housing material upper part:	PC
Connection terminal:	Cage clamp terminal
Terminal style:	fixed
Height dimension:	129
Width dimension:	12.6
Net weight:	37
Gross weight:	48

Environment

RoHS directive:	2011/65/EU, 2015/863/EU
-----------------	-------------------------


RoHS conformity:	yes
RoHS exceptions:	yes
RoHS except.s acc. to direct.:	6c
REACH compliance:	contains min. 1 SVHC-substance
REACH included substances:	Lead
%-part of the pollutant:	> 0,1%
CAS No.:	7439-92-1
WEEE classification (08/2018):	5 devices (feed size < 50cm)
SCIP entry available:	yes
Commercial data	
Harmonized System Code:	85369095
UNSPSC 25:	39122331
EAN-Code:	4046548056778
ECLASS version:	ECLASS-13
ECLASS Reference Feature:	27242603
ETIM Version:	ETIM-9.0
ETIM Reference Group:	EG000024
ETIM Reference Feature:	EC001598
Volume:	0

Optional accessories

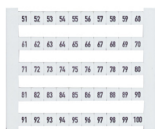

312960

PSSu A LA2 (10x50 pcs.)

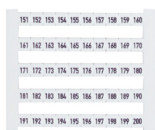


312962

PSSu A LA4 (10x50 pcs.)



312951

PSSu A ME1 (10x6 pcs.)

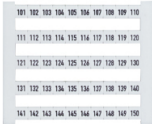

312961

PSSu A LA3 (10x50 pcs.)



312950

PSSu A ME0 (10x6 pcs.)



312953

PSSu A ME3 (10x6 pcs.)



312952

PSSu A ME2 (10x6 pcs.)



312963

PSSu A SH S (10 pcs.)



312955

PSSu A ME5 (10x6 pcs.)



312900

PSSu A ET (10 pcs.)



312954

PSSu A ME4 (10x6 pcs.)



312957

PSSu A ME7 (10x6 pcs.)



312902

PSSu A EC



312956

PSSu A ME5 (10x6 pcs.)



312967

PSSu A LA0.1 (10 x 108 pcs.)



312901

PSSu A ETM (2 pcs.)



312959

PSSu A LA1 (10x50 pcs.)



312958

PSSu A LA0 (10 x 108 pcs.)



312949

PSSu A ET PE (10 pcs.)