



PSSu, base module for supply voltage modules, infeed module supply, infeed periphery supply, infeed C-rail, 2-row, 4 connection levels, 8 terminals, screw connection. Only for use as first module after the head module in system environment A and after the remote station PSSu XR F-T!

Technical details

General data	
Approval:	CE, UKCA,
Application range:	Standard/failsafe
Technical data	
Environmental data	
Humidity rating:	93 % r. h. at 40 °C
Mechanical data	
Housing material lower section:	PA
Housing material upper part:	PC
Connection terminal:	Screw terminal
Terminal style:	fixed
Height dimension:	129 mm
Width dimension:	25.2 mm
Net weight:	71 g
Gross weight:	86 g
Environment	
RoHS directive:	2011/65/EU, 2015/863/EU
RoHS conformity:	yes
RoHS exceptions:	yes
RoHS except.s acc. to direct.:	6C


REACH compliance:	contains min. 1 SVHC-substance
REACH included substances:	Lead
%-part of the pollutant:	> 0,1%
CAS No.:	7439-92-1
WEEE klassifikation (08/2018):	5 devices (feed size < 50cm)
Commercial data	
Harmonized System Code:	85369010
EAN-Code:	4046548018356
ECLASS version:	ECLASS-13
ECLASS Reference Feature:	27242603
ETIM Version:	ETIM-9.0
ETIM Reference Group:	EG000024
ETIM Reference Feature:	EC001598
Volume:	0 dm3

Optional accessories



312960

PSSu A LA2 (10x50 pcs.)

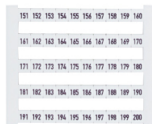


312962

PSSu A LA4 (10x50 pcs.)



312951

PSSu A ME1 (10x6 pcs.)

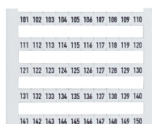

312961

PSSu A LA3 (10x50 pcs.)

	312950	PSSu A ME0 (10x6 pcs.)
	312953	PSSu A ME3 (10x6 pcs.)
	312952	PSSu A ME2 (10x6 pcs.)
	312963	PSSu A SH S (10 pcs.)
	312955	PSSu A ME5 (10x6 pcs.)
	312900	PSSu A ET (10 pcs.)
	312954	PSSu A ME4 (10x6 pcs.)
	312957	PSSu A ME7 (10x6 pcs.)
	312902	PSSu A EC



312956

PSSu A ME5 (10x6 pcs.)




312967

PSSu A LA0.1 (10 x 108 pcs.)



312901

PSSu A ETM (2 pcs.)

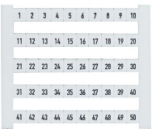

312959

PSSu A LA1 (10x50 pcs.)



312958

PSSu A LA0 (10 x 108 pcs.)



312949

PSSu A ET PE (10 pcs.)