

## PSSu BP-C 1/8 S-T

314610



PSSu, base module for electronic modules, periphery, C-rail, 1-row, 4 connection levels, 8 terminals, screw connection, for increased environmental requirements.

## Technical details

### General data

Approval: CE, UKCA, UL Recognized Component

Application range: Standard/failsafe

### Technical data

### Environmental data

Humidity rating: 93 % r. h. at 40 °C

Condensation permitted?: Briefly

Perm. operating height ASL: 5000 m

### Mechanical data

Housing material lower section: PA

Housing material upper part: PC

Connection terminal: Screw terminal

Terminal style: fixed

Height dimension: 129 mm

Width dimension: 12.6 mm

Net weight: 52 g

Gross weight: 63 g


### Environment

WEEE classification (08/2018): 5 devices (feed size < 50cm)

### Commercial data


ECLASS version:	ECLASS-13
ECLASS Reference Feature:	27242603
ETIM Version:	ETIM-9.0
ETIM Reference Group:	EG000024
ETIM Reference Feature:	EC001598
UNSPSC 25:	39122331
GTIN:	4046548054323
Volume:	0 dm3
Harmonized System Code:	85369095
Type of tariff number:	TARIC
Use of customs tariff number:	Ausfuhr, Einfuhr
Quantity per packaging unit:	1

## Optional accessories

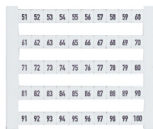

312960

PSSu A LA2 ( 10x50 pcs.)

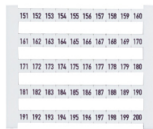


312962

PSSu A LA4 (10x50 pcs.)



312951

PSSu A ME1 (10x6 pcs.)

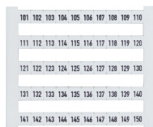

312961

PSSu A LA3 (10x50 pcs.)



312950

PSSu A ME0 (10x6 pcs.)


	312953	PSSu A ME3 (10x6 pcs.)
	312952	PSSu A ME2 (10x6 pcs.)
	312955	PSSu A ME5 (10x6 pcs.)
	312900	PSSu A ET (10 pcs.)
	312954	PSSu A ME4 (10x6 pcs.)
	312957	PSSu A ME7 (10x6 pcs.)
	312956	PSSu A ME5 (10x6 pcs.)
	314902	PSSu A EC-T
	312967	PSSu A LA0.1 (10 x 108 pcs.)



312901

PSSu A ETM (2 pcs.)

---

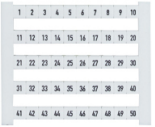

312959

PSSu A LA1 (10x50 pcs.)

---



312958

PSSu A LA0 (10 x 108 pcs.)

---



312949

PSSu A ET PE (10 pcs.)

---