

## PSSu BS-R 1/8 C-T

314653




PSSu, base module for supply voltage modules, infeed module supply, infeed periphery supply, infeed C-rail, 1-row, 4 connection levels, 8 terminals, spring-loaded connection, for increased environmental requirements. Only to refresh the supply voltage and to form supply groups!

## Technical details

General data	
Approval:	CE, UKCA, TÜV
Application range:	Standard/failsafe
Technical data	
Environmental data	
Humidity rating:	93 % r. h. at 40 °C
Condensation permitted?:	Briefly
Perm. operating height ASL:	5000 m
Mechanical data	
Housing material lower section:	PA
Housing material upper part:	PC
Connection terminal:	Cage clamp terminal
Terminal style:	fixed
Height dimension:	129 mm
Width dimension:	12.6 mm
Net weight:	37 g
Gross weight:	49 g
Environment	
RoHS directive:	2011/65/EU, 2015/863/EU
RoHS conformity:	yes


RoHS exceptions:	no
REACH compliance:	Contains no SVHC substances
WEEE classification (08/2018):	5 devices (feed size < 50cm)
<b>Commercial data</b>	
Harmonized System Code:	85369095
UNSPSC 25:	39122331
EAN-Code:	4046548054453
ECLASS version:	ECLASS-13
ECLASS Reference Feature:	27242603
ETIM Version:	ETIM-9.0
ETIM Reference Group:	EG000024
ETIM Reference Feature:	EC001598
Volume:	0 dm3

## Optional accessories

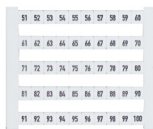

312960

PSSu A LA2 ( 10x50 pcs.)

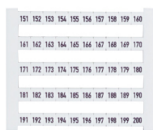


312962

PSSu A LA4 (10x50 pcs.)



312951

PSSu A ME1 (10x6 pcs.)

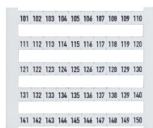

312961

PSSu A LA3 (10x50 pcs.)

	312950	PSSu A ME0 (10x6 pcs.)
	312953	PSSu A ME3 (10x6 pcs.)
	312952	PSSu A ME2 (10x6 pcs.)
	312955	PSSu A ME5 (10x6 pcs.)
	312900	PSSu A ET (10 pcs.)
	312954	PSSu A ME4 (10x6 pcs.)
	312957	PSSu A ME7 (10x6 pcs.)
	312956	PSSu A ME5 (10x6 pcs.)
	314902	PSSu A EC-T



312967

PSSu A LA0.1 (10 x 108 pcs.)

---



312901

PSSu A ETM (2 pcs.)

---



312959

PSSu A LA1 (10x50 pcs.)

---



312958

PSSu A LA0 (10 x 108 pcs.)

---



312949

PSSu A ET PE (10 pcs.)

---