


PSEN ma1.4-10mm 1actuator

506301

Actuator for magnetic safety switch, square design, IP67, operating distance 10 mm, height design 18 mm, PU = 1 actuator.

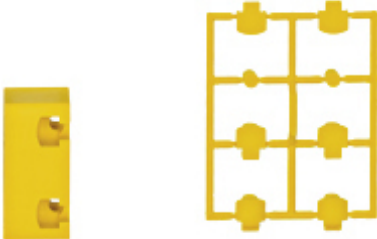

Technical details

General data	
Approval:	CE, UKCA, cULus Listed, EAC (Eurasian), TÜV
unit type:	Actuator
Technical data	
Environmental data	
Ambient temperature:	-10 - 55 °C
Max. ambient temp. at 2000 m:	+55 °C
Perm. operating height ASL:	4000 m
EMC to standard ...:	EN 60947-5-3
Vibration to standard ...:	EN 60947-5-2
Acc. shock to standard1:	30g
Pollution degree clear.&creep.:	3
Mechanical data	
Housing material upper part:	PBT
Height dimension:	37 mm
Width dimension:	18 mm
Depth dimension:	18 mm
Net weight:	17 g
Gross weight:	22 g
Environment	

WEEE classification (08/2018):	5 devices (feed size < 50cm)
Commercial data	
ECLASS version:	ECLASS-13
ECLASS Reference Feature:	27274002
ETIM Version:	ETIM-9.0
ETIM Reference Group:	EG000026
ETIM Reference Feature:	EC001487
UNSPSC 25:	39122205
GTIN:	4046548060225
Volume:	0 dm3
Harmonized System Code:	85389099
Type of tariff number:	TARIC
Use of customs tariff number:	Ausfuhr, Einfuhr
Quantity per packaging unit:	1