


PSEN rsm 1.0-300-0-2-0

570307

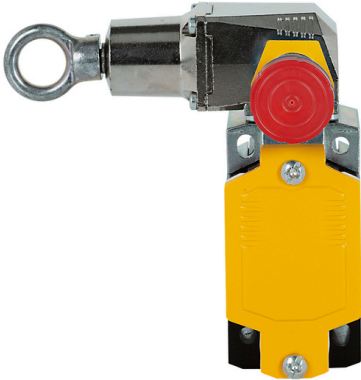

Rope pull switch incl. E-STOP pushbutton, angled head left, metal housing, 2 NC and 2 NO contacts, 300 N max. spring force

Technical details

General data	
Approval:	CCC, CE, cULus Listed
Technical data	
Relay outputs	
Utilisation cat. AC15/DC13sta.:	EN 60947-5-1
Voltage AC15 safety cont.:	240 V
Max. current AC15 safety cont.:	3 A
Voltage DC13 safety cont.:	250 V
Environmental data	
Ambient temperature:	-30 - 75 °C
Mechanical data	
Housing material lower section:	Aluminium die cast
Housing material upper part:	Aluminium die cast
Material actuator:	Zn die cast
Connection terminal:	Screw terminal
Height dimension:	115 mm
Width dimension:	111 mm
Depth dimension:	67 mm
Net weight:	464 g
Gross weight:	611 g

Environment	
RoHS directive:	2011/65/EU, 2015/863/EU
RoHS conformity:	yes
RoHS exceptions:	no
REACH compliance:	Contains no SVHC substances
WEEE classification (08/2018):	5 devices (feed size < 50cm)
Commercial data	
ECLASS version:	ECLASS-13
ECLASS Reference Feature:	27270607
ETIM Version:	ETIM-9.0
ETIM Reference Group:	EG000017
ETIM Reference Feature:	EC002033
UNSPSC 25:	39122205
GTIN:	4046548104936
Volume:	3.520 dm3
Harmonized System Code:	85365080
Type of tariff number:	TARIC
Use of customs tariff number:	Ausfuhr, Einfuhr
Quantity per packaging unit:	1

Optional accessories



570318

PSEN rsm rope thimble



570319

PSEN rsm rope clamp



570316

PSEN rsm turnbuckle



570314

PSEN rs rope d3/d4 50m



570315

PSEN rs rope d3/d4 100m



570312

PSEN rs pulley 75



570313

PSEN rs pulley flex



570311

PSEN rs spring 300



570793

PSEN cable 200m-8x0.25mm²
