


PNOZ XV2.1P 30/24-240VACDC 2n/o 2n/o t

777540

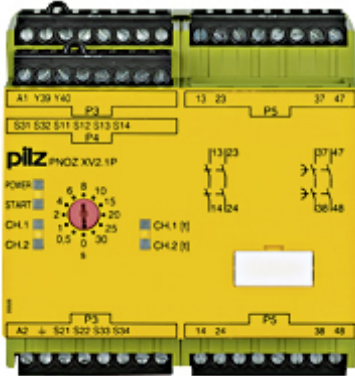

Safety relay (standalone), inputs: 1/2-channel wiring with/without detection of shorts across contacts, outputs: 2 N/O, 2 N/Ot-d (t = 0.1 - 30 s), automatic/monitored start, UB 24 - 240 V AC/DC, width: 90 mm, plug-in terminals of screw type, monitoring of E-STOP, safety gates, feedback loop. This product has been discontinued. The following products are fully compatible in function: 750105 751105 750135 751135 However, it should be checked for the respective application whether all necessary framework conditions and parameters are also fulfilled for the intended use.

Technical details

General data

Approval: CCC, CE, UKCA, cULus Listed, EAC (Eurasian), TÜV

Technical data

Environment

RoHS directive: 2011/65/EU, 2015/863/EU

RoHS conformity: yes

RoHS exceptions: yes

RoHS except.s acc. to direct.: 7a, 6c, 7c I

REACH compliance: contains min. 1 SVHC-substance

REACH included substances: Lead, Lead oxide

%-part of the pollutant: > 0,1

CAS No.: 7439-92-1, 1317-36-8

SCIP entry available: yes

WEEE classification (08/2018): 5 devices (feed size < 50cm)

Commercial data

ECLASS version: ECLASS-13

ECLASS Reference Feature: 27371819

ETIM Version: ETIM-9.0

ETIM Reference Group: EG000019

ETIM Reference Feature: EC001449

UNSPSC 25:	39122331
GTIN:	4046548009446
Volume:	0.605 dm3
Harmonized System Code:	85364900
Type of tariff number:	TARIC
Use of customs tariff number:	Ausfuhr, Einfuhr

Optional accessories

374282

PNOZ X Set plug in screw terminals P5+P5



374281

PNOZ X Set plug in screw terminals P3+P4

