


PLID d1 C

784260

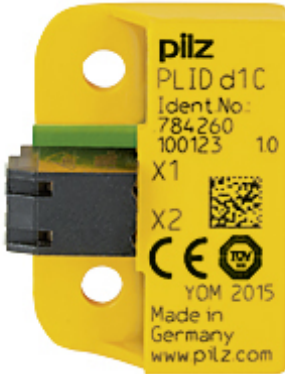

PNOZ, accessories, safe line inspection of a 2-wire line for short circuit, short across contacts and open circuit, test pulse signalinput for evaluation device PNOZ e8.1p, manual test with 1N/O contact, continuous test with 1N/C, maximum cable length 3000 m, version with spring-loaded terminal.

Technical details

General data	
Approval:	CE, UKCA, cULus Listed, TÜV
Technical data	
Electrical data	
Source of internal voltage:	Via evaluation device
Environmental data	
Climatic suitability to ...:	EN 60068-2-78
Ambient temperature:	-30 - 70 °C
Humidity rating:	93 % r. h. at 40 °C
Condensation permitted?:	Not permitted
EMC to standard ...:	EN 60947-5-1, EN 61000-6-2, EN 61000-6-4
Vibration to standard ...:	EN 60068-2-6
Clearance & creepage dist. to:	EN 60947-1
Overvoltage category:	III
Pollution degree clear.&creep.:	2
Mechanical data	
Mounting position:	any
Max. cable length:	3000 m
Housing material lower section:	PC
Connection terminal:	Spring-loaded terminal

Terminal style:	fixed
Height dimension:	36 mm
Width dimension:	30 mm
Depth dimension:	12.5 mm
Net weight:	10 g
Gross weight:	28 g
Environment	
REACH compliance:	contains min. 1 SVHC-substance
WEEE classification (08/2018):	5 devices (feed size < 50cm)
Commercial data	
Harmonized System Code:	85389091
UNSPSC 25:	39122331
EAN-Code:	4046548067118
ECLASS version:	ECLASS-13
ECLASS Reference Feature:	27141990
ETIM Version:	ETIM-9.0
ETIM Reference Group:	EG000019
ETIM Reference Feature:	EC002586
Volume:	0.248 dm ³